

# Connecting Parts / Linkage Parts

## Connecting Parts Linkage Parts



Product Name	Link Cable / Wire	Rod End Coupling Rods	Rod End Bearings / Link Ball	Spherical Bearing
Page	1561	1563	1565, 1566	1567



Spherical Bearing Holder Sets	Hinge Bolt	Hinge Bases - Fixed	Hinge Plates	Hinge Bases - Standard
1567	1568	1569	1570	1571, 1572



Hinge Bases - H Compact Type	A Compact / A, H Compact	Thick Type	Bottom Side Mounting	Side Mounting
1573	1574	1575, 1576	1577, 1578	1579, 1580



Hinge Bases - Center Mounting	Center Fulcrum, 2 Point Mounting	Center Fulcrum 4 Mounting Points	L-Shaped Fulcrum Type	L-Shaped Fulcrum, Thick
1581	1582	1583, 1584	1585	1586



Knuckle Joints - Extra Short	Tool-Less	Fixed	B Selectable	Configurable
1587	1587	1588	1588	1589-1590











 
 
 
 
 


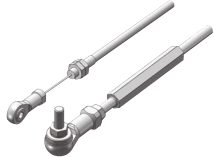

 


 





 





 
 
 

 

 

 
 

 
 

 

 



 

 
 
 
 





Links	Bearing Embedded	Oil Free Bushings Press Fit	Notched
1591-1594	1595	1596	1597



Links - Slotted Hole	Link Bars	General Purpose	Clamp Links
1597	1598	1599	1600

# Connecting Parts / Linkage Parts Guide

Component Name	Characteristics (Shape / Installation)			Combination Examples
Connecting Components	Flexible		Rigid	
	<b>Link Cable</b>  <b>Link Wire</b> 	Both Ends Threaded  Both Ends Tapped  One End Threaded / One End Tapped 		
End Components	<b>Hinge Bolt</b> Standard  Type R 	<b>Rod End Bearings</b> Tapped Type  Threaded Type  Link Ball L  Straight 	<b>Spherical Bearing</b> Holder Set  Bearing 	 <b>#MA561</b> <b>πType Hinge Base Connection Type</b> <Connection Type> Rod End Bearings Hinge Base - Compact, U-Shaped Hinge Pin - Shouldered Retaining Ring Hex Socket Head Cap Screw
Hinge Bases	<b>Raised Track</b> Standard  Bottom Side Mounting  Side Mounting  2 Point Mounting  4 Point Mounting  L-Shaped  2 Point Mounting  4 Point Mounting 	<b>Channel</b> Standard  Bottom Side Mounting  Side Mounting  2 Point Mounting  4 Point Mounting  L-Shaped  2 Point Mounting  4 Point Mounting  Center Mounting  Bottom Side Mounting 	<b>Plate</b> Hinge Plates  Hinge Plates - Type R  Hinge Plates - Economy Type 	 <b>#MA512</b> <b>Quick Connection Type - A Compact</b> <Connection Type> Hinge Base - T-Shaped Hinge Base - Bottom Mount, U-Shaped Hinge Pin - Shouldered Retaining Ring Hex Socket Head Cap Screw  <b>#MA513</b> <b>Quick Connection Type - H Compact</b> <Connection Type> Hinge Base - H Compact, T-Shaped Hinge Base - H Compact, U-Shaped Hinge Pin - Shouldered Retaining Ring Hex Socket Head Cap Screw
<b>Knuckle Joints</b>  <b>Link Bars</b> 	<b>Raised Track</b> Tapped Type  Threaded Type     	<b>Channel</b> Tapped Type  Threaded Type     	<b>Unit</b> Extra Short Type  	 <b>#MA601</b> <b>πType Hinge Base Connection Type</b> <Connection Type> Knuckle Joint - Threaded, Configurable Hinge Base - Compact, T-Shaped Hinge Pin - Shouldered Retaining Ring Hex Socket Head Cap Screw
Links	<b>2-Hole</b> Standard / Economy  Bearing (Bearing / Oil Free Bushing)  Clamp  General Purpose 	<b>3-Hole</b> Standard  Precision Holes / Side Tapped 	<b>Notched, Slotted Hole, Angled</b> Notched  Slotted Hole  Angled 