


Posts, Post Stands, Strut Clamps

Hex Posts

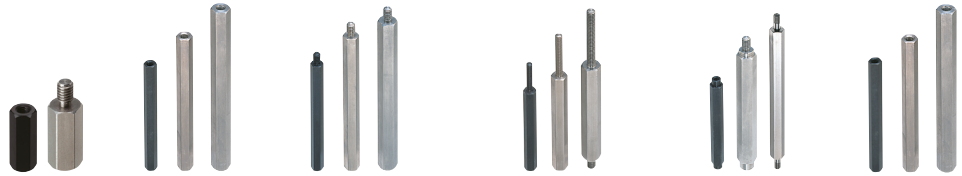

Product Name	Small Dia. Hex Posts	Hex Posts - Both Ends Tapped	One End Threaded One End Tapped	One End Threaded One End Tapped / Both Ends Threaded, Thread Length & Dia. Configurable	Pilot Selectable / Configurable	Hex Posts - One End Tapped
Page	2116	2117	2119	2121	2123	2125



Circular Posts / Square Post



One End Threaded	Attachment Blocks for Hex Posts	Circular Posts - Both Ends Tapped, Wrench Flats	One End Threaded One End Tapped, Wrench Flats	One End Threaded One End Tapped / Both Ends Threaded, Thread Length & Dia. Configurable, Wrench Flats
2125	2126	2127	2129	2131



Circular Posts - Pilot Selectable / Pilot & Wrench Flats Configurable	One End Tapped / One End Threaded	Plastic Circular Posts - One End Tapped / Both Ends Tapped	Square Posts - Both Ends Tapped, One End Threaded One End Tapped	Spacer Blocks	Posts for Stands
2133	2135	2136	2137	2139	2143


Posts for Stands Device Stands



Caps for Hollow Posts	Posts for Stands - With Scale	Length Configurable with Scale	Device Stands - Compact	Compact, Slotted Hole	Round Flanged	Square Flanged
2143	2144	2144	2145	2146	2147	2149



Square Flanged, Slotted Holes	Side Mounting, Compact	Side Mounting	Stand-Up Brackets - Economy Type	Standard Type	Stand-Up Brackets - Cylindrical
2150	2151	2152	2153	2153	2154

 

Reversed Fastening	Square Standard	Square Right/Left Reversed	Square Compact	Non-Flanged Side Mounting	Side Mounting	Side Mounting, Dowel Hole
2154	2155	2155	2156	2156	2157	2157



Side Mounting, Compact	Side Mounting, Casting	Side Mounting, Casting, Dowel Holes	Side Mounting, Slotted Holes	Posts for Stands - Square Bars, Square Tubes	Length Configurable with Scale	Square Hole - Standard	Square Hole - Side Mounting Holes
2157	2158	2158	2158	2159	2159	2160	2160

Strut Clamps



Round Strut Clamp - Equal Dia., Perpendicular Configuration	Strut Clamps - Equal Dia., Perpendicular Configuration / Reversed	Super Compact Strut Clamps - Equal / Unequal Dia., Perpendicular Configuration	Resin - Equal Dia., Perpendicular Configuration	Super Compact Strut Clamps - Equal / Unequal Dia., Perpendicular Configuration with Wing Knobs
2163	2164	2165	2165	2166




Strut Clamps - Equal Dia., Perpendicular Configuration with Clamp Levers	Compact Strut Clamps - Equal Dia., Perpendicular Configuration	Unequal Dia., Perpendicular Configuration	Unequal Dia., Perpendicular Configuration / Reversed	Perpendicular Configuration, Hole Pitch Selectable	Height Adjustment Screw Set for Strut Clamps
2166	2167	2167	2168	2169	2170




Split, (Equal/Unequal Dia., Perpendicular Configuration)	Equal Dia., Perpendicular Configuration, Split, T-Shaped	Parallel Holes, Pitch Selectable	Equal Dia., Rotation	Unequal Dia., Rotation	Square / Round Hole, Rotation
2171	2171	2172	2173	2173	2174



Super Compact Strut Clamps - Vertical / Parallel Taps with Wing Knobs	(Vertical / Parallel Taps)	With Clamp Lever (Vertical / Parallel Taps)	Vertical Taps	Parallel Taps	Split (Vertical/Parallel Taps)
2175	2175	2176	2177	2178	2179

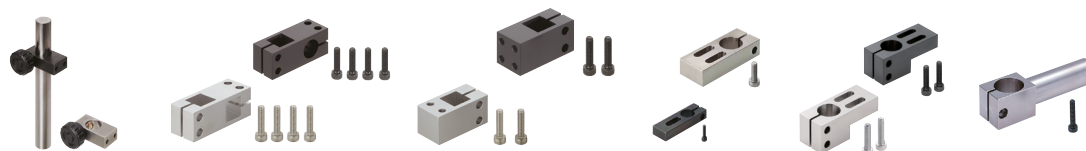

Strut Clamps - Anti-Rotation, Parallel Taps	Square & Round / Square & Square, Perpendicular Configuration	Vertical / Parallel Taps, Square Hole	Slotted Hole	L-Shaped	Arm
2180	2181	2182	2183	2183	2184

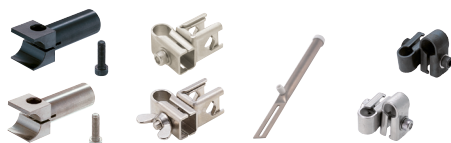

Hollow Stands Rotary Connectors



Bar Clamps	Flexible Clamps	Holder Pipes	Flexible Clamps - Compact	Hollow Stands - Set Screw	Welded	Hollow Stands - Pipe Threaded
2184	2185	2185	2186	2187	2188	2189



Pipe Threaded, Welded	Rotary Connectors - Round Flanged / Compact Flanged	Moment Load Allowable - Single Flanged, Double Flanged	Height Adjusting Toggle Clamp	Device Stand Set	Square Post Stand Set
2189	2191	2192	2139	2148	2174