

Rollers & Conveyor Components

Rollers & Conveyor Components



Product Name	Rollers - Straight / Crowned -	Rollers - With Bearings -	Rollers - Urethane Thickness Selectable -	Resin Rollers
Page	1119	1121	1123	1124



Core Material Press Fit Straight Type -	With Core Material Press Fit with Bearings -	Hollow Aluminum Rollers	Rollers -Tapped Straight / Crowned Type -	Rollers - Set Screw Holes -
1125	1126	1126	1127	1128



Rollers - With Keyway -	Keywayed and Tapped	Grooved Rollers	With Bearings -	Vertical Guide Rollers - Core Material / Urethane Type -	Rollers with Oil Free Bushings - Core Material / Urethane Type -	Side Through Hole Rollers
1129	1129	1130	1130	1131	1131	1132



Expanded Spec.



End Feed Rollers	Urethane Rollers with Collars	Knurled Urethane Rollers - Set Screw Type -	Bearing Adhesive Integrated Urethane Rollers	Urethane Rollers - Set Screw Type -	Knurled Urethane Rollers	Hollow Rollers - Straight -
1132	1133	1133	1134	1134	1134	1135



With Bearings -	Economy Type -	Pipe Roller with One Way Clutch -	Set Screw Type -	Long Hollow Rollers	Hollow Rollers with Shafts	Precision Rollers	Urethane Rollers with Shafts
1136	1137	1138	1139	1140	1141	1142	1143



Both Ends Threaded -	Urethane Thickness Configurable -	Belt Tensioners - Screw Type -	Spring-Loaded -	Urethane Molded Bearings - Protruded Inner Ring -	Urethane Press-Fit Bearings	Silicon Rubber / Urethane Molded Bearings -	R Type -
1143	1144	1145	1147	1149	1149	1151	1152



Hubbed Type -	Threaded Flat Type -	Threaded R Type -	Threaded Bearings	Urethane Molded Bearing Shafts	Eccentric Bushings	Cantilever Rollers	Engineered Plastic Bearings - Antistatic -
1152	1153	1154	1155	1155	1155	1156	1157



Flat Type -
1157



Engineered Plastic Bearings - R Type -
1157



With Bracket -
1158



Engineered Plastic Bearings - U Groove -
1158



V Groove Type -
1158



One Side Flanged -
1158



Guide Rollers
1159, 1160



Motor Rollers
1162



Conveyor Rollers Urethane Lined Type -
1163



Conveyor Rollers - Shaft & Roller Sets -
1164



Roller with Sprocket
1164



Plastic Conveyor Rollers
1164



 
Conveyor Roller Shafts
1165



Miniature Conveyor Rollers
1165



Resin Conveyor Rollers DIA. 20, 30, 50mm -
1167




Roller Conveyors
1168 / 1169



Conveyor Wheels
1171



Rubber and Urethane Lined Wheels for Conveyors
1171

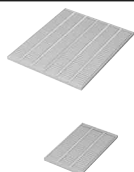

Miniature Roller Panels -
1172



Miniature Roller Chutes -
1172



Roller Carriers - Cantilever Type -
1173



Zigzag Type -
1174



Roller Width 7-9 / 15 / 25mm Milled -
1175 ~ 1178



With Bracket -
1175 ~ 1178



Press Formed Rollers / Urethane Rollers -
1176



Roller Width 50mm Type -
1178



Ball Rollers - Hex Head Stud -
1179



Press Fit -
1179



Insertion / Adhesive Type -
1179



Plunger Type Ball Rollers / Press Fit -
1179



Threaded Type -
1179



Nut Mount / Flange Mounting Type -
1180



Set Screw Type -
1180



Round Bolt -
1180



Ball Roller Units
1181



Ball Rollers - Milled Steel Type -
1182



Steel Press Formed Type -
1182



Engineering Plastic Rails - Flat Type -
1183



Engineering Plastic Rails - Shaped Type -
1185




Slide Tapes / Strong Double-Sided Tapes
1186



Guide Rails
1186



Stainless Steel Sliding Plates
1187

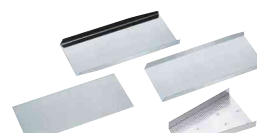

Product Chute Thin Plates
1187